

Self Tapping Screws

Spring Washers / Flat Washers

 
Available in Box

Self Tapping Screws - Pan Head



RoHS

TANB
TANBS



Type	Material	Surface Treatment
TANB	JIS-SWCH Equiv.	Trivalent Chromate
TANBS	EN 1.4301 Equiv.	-

M	A	E	Phillips No.
3	5.5	2.0	2
3.5	6.0	2.3	2
4	7.0	2.6	2
5	9.0	3.3	2

Part Number		TANB				TANBS			
Type	M-L	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~249	250~500	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~149	150~500
TANB TANBS	3 - 5					-	-	-	-
	6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	3.5 - 6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
4	4 - 6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
5	5 - 8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
	20					-	-	-	-



Ordering
Example


Part Number
TANBS4-10

Self Tapping Screws - Flat Head



RoHS

TASA
TASAS

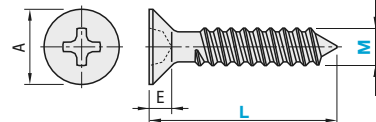

Type	Material	Surface Treatment
TASA	JIS-SWCH Equiv.	Trivalent Chromate
TASAS	EN 1.4301 Equiv.	-

M	A	E	Phillips No.
3	6.0	1.75	2
3.5	7.0	2.00	2
4	8.0	2.30	2
5	10.0	2.80	2

Part Number		TASA				TASAS			
Type	M-L	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~249	250~500	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~149	150~500
TASA TASAS	3 - 6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	3.5 - 8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
	4 - 8					-	-	-	-
	10					-	-	-	-
5	5 - 10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
	20					-	-	-	-



Ordering
Example


Part Number
TASAS4-10

Self Tapping Screws - Truss Head



RoHS

TATR
TATRS

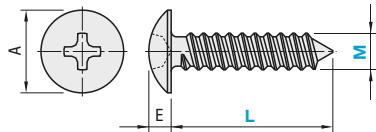

Type	Material	Surface Treatment
TATR	JIS-SWCH Equiv.	Trivalent Chromate
TATRS	EN 1.4301 Equiv.	-

M	A	E	Phillips No.
3	6.9	1.9	1
3.5	8.1	2.2	2
4	9.4	2.5	2
5	11.8	3.1	2

Part Number		TATR				TATRS			
Type	M-L	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~249	250~500	Unit Price 1 ~ 29 pc(s).	Volume Discount Rate 30~99	100~149	150~500
TATR TATRS	3 - 6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	3.5 - 6					-	-	-	-
	8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
	4 - 6					-	-	-	-
5	5 - 8					-	-	-	-
	10					-	-	-	-
	12					-	-	-	-
	16					-	-	-	-
	20					-	-	-	-



Ordering
Example

Part Number
TATRS5-10

Spring Washers




RoHS

Spring Washers

Type	Material	Surface Treatment
BOX-SLW	JIS-SWHR57	Trivalent Chromate
BOX-SSLW	EN 1.4301 Equiv.	-

BOX-SLW
BOX-SSLW

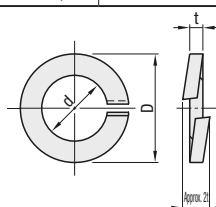

No.	d	D	t
3	3.1	5.9	0.7
4	4.1	7.6	1
5	5.1	9.2	1.3
6	6.1	12.2	1.5
8	8.2	15.4	2
10	10.2	18.4	2.5
12	12.2	21.5	3

Can be ordered as a separate item. P237




RoHS

Flat Washers

Type	Material	Surface Treatment
BOX-PWF	EN 1.0330 Equiv.	Trivalent Chromate
BOX-SPWF	EN 1.4301 Equiv.	-

BOX-PWF
BOX-SPWF

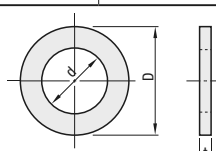

No.	d	D		t
		BOX-PWF	BOX-SPWF	
3	3.2	6	7	0.5
4	4.3	8	9	0.8
5	5.3	10	10	1
6	6.4	12.5	12.5	1.6
8	8.4	15.5	17	1.6
10	10.5	18	21	2
12	13.0	21	24	2.5

Can be ordered as a separate item. P237

Please specify in box quantity when ordering.
One box is shipped for an order of 1.



Ordering
Example

Part Number
BOX-SSLW8
BOX-PWF3

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	No.	Price per pkg.	1 Box	
BOX-SLW	3			2,000 pcs./box
	4			
	5			
	6			
	8			1,000 pcs./box
	10			
	12			700 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	No.	Price per pkg.	1 Box	
BOX-SSLW (Stainless Steel)	3			2,000 pcs./box
	4			
	5			
	6			
	8			1,000 pcs./box
	10			
	12			700 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	No.	Price per pkg.	1 Box	
BOX-PWF	3			2,000 pcs./box
	4			
	5			
	6			
	8			1,000 pcs./box
	10			
	12			700 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	No.	Price per pkg.	1 Box	
BOX-SPWF (Stainless Steel)	3			2,000 pcs./box
	4			
	5			
	6			
	8			1,000 pcs./box
	10			
	12			700 pcs./box

For orders larger than indicated quantity, please check with WOS.