


OIL-FREE GUIDE POST SETS

—PRESS-FIT TYPE—

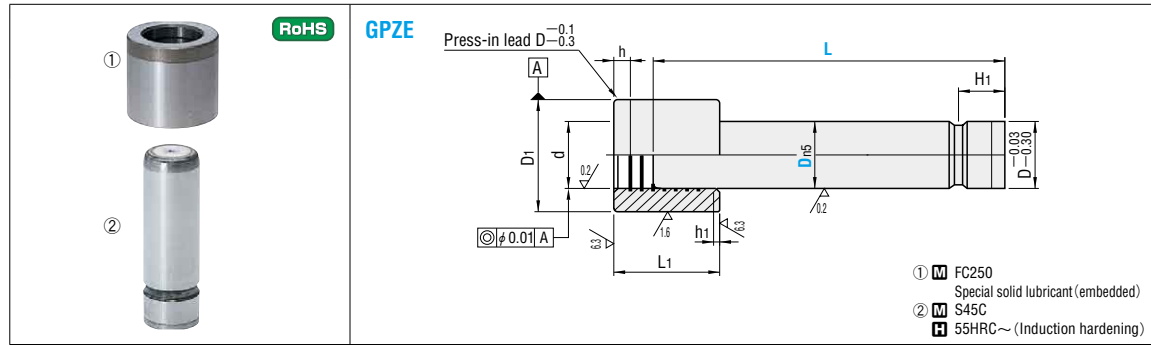

Dn5	H1	d	D _{1JS5}		h	h1	L1
			Type	GPZE			
32	20	32	+0.047 +0.037	52	8	4	48
38	25	38	+0.049 +0.037	60	10	5	55
50	32.5	50	+0.052 +0.037	70	15	10	75
60	37.5	60	+0.061 +0.043	80	20	10	90
80	50	80	+0.063 +0.043	100	25	10	120

D1	Catalog No.		L	Base unit price 1~9 pieces
	Type	D		
52	GPZE	32	90 100 110 120 130 140 150 160 170 180 200 220 250	Quotation
60		38	110 120 130 140 150 160 170 180 200 220 250 280 300	
70		50	160 170 180 200 220 250 280 300 350	
80		60	180 200 220 250 280 300 350 400	
100		80	250 280 300 350	
			400 450	

Order **Catalog No.** — **L**
GPZE 80 — 300 **P** Price **Quotation**


Days to Ship **Quotation**

Alterations **Catalog No.** — **L(LC)**
GPZE 80 — LC 290 **Quotation**

Alteration	Code	Spec.	D		1Code
			D	LCmin.	
	LC	Post length change $LCmin. \leq LC < Lmax.$ 1mm increments	32	85	32 38·50 60·80 Quotation
			38	105	
			50	140	
			60	165	
			80	220	

OIL-FREE GUIDE BUSHINGS

—PRESS-FIT TYPE—

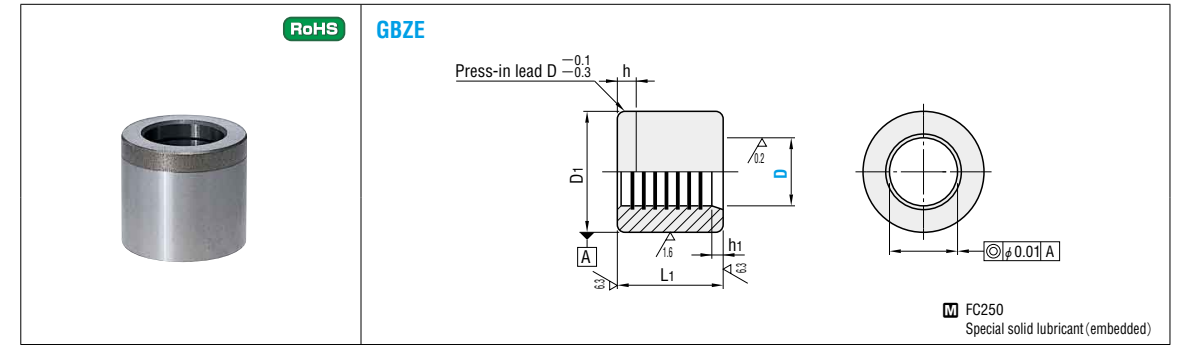

Type	Catalog No.		D _{1JS5}	h	h1	L1	Base unit price 1~9 pieces
	Type	D					
GBZE	32	+0.047 +0.037	52	8	4	48	Quotation
	38	+0.049 +0.037	60	10	5	55	
	50	+0.052 +0.037	70	15	10	75	
	60	+0.061 +0.043	80	20	10	90	
	80	+0.063 +0.043	100	25	10	120	

Order **Catalog No.** — **P** Price **Quotation**
GBZE 50

Days to Ship **Quotation**

HOLDER GUIDE
POST SETS