

## Prismen

1148.200




### Produktbeschreibung

#### Werkstoff

- Stahl, Einsatzgehärtet, geschliffen

### Maßzeichnung

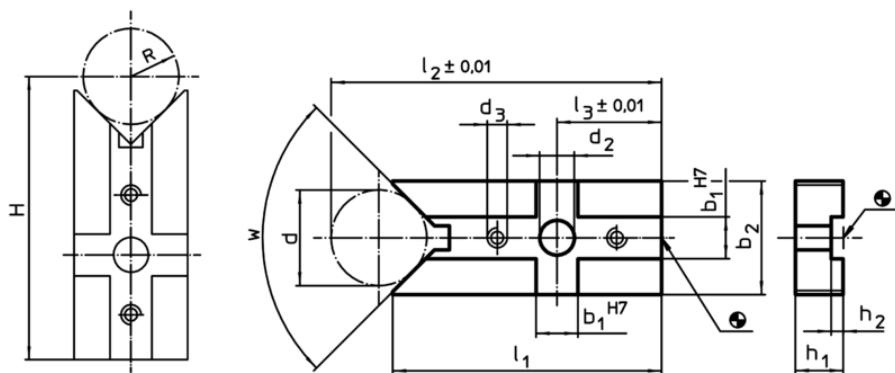

$$\begin{aligned}
 H &= (R \cdot 1,414) + 49,497 \quad [1048.200] \\
 H &= (R \cdot 1,414) + 48,996 \quad [1048.300] \\
 H &= (R \cdot 1,155) + 77,025 \quad [1148.000] \\
 H &= (R \cdot 1,155) + 81,204 \quad [1148.100] \\
 H &= (R \cdot 1,414) + 72,872 \quad [1148.200] \\
 H &= (R \cdot 1,414) + 73,159 \quad [1148.300]
 \end{aligned}$$

### Bestellinformationen

System	Abmessungen											w		Art.-Nr.	
	b <sub>1</sub>	d	b <sub>2</sub>	d <sub>2</sub>	d <sub>3</sub>	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	d min.				
[mm]													[g]		
V70	14	32	38	13	M6	90	111,5	35	16	4	14	44	90°	325	1148.200

### Anwendungsbeispiel

